

Part No: S1580C30FSR

Valves

Swing & Spring Check

Desc: 3 PVC CL UTILITY SPRG CHK VLV SRTHD EPDM

MSRP: 286.47

Part Code: 026

Weight(lbs): 3.007


Weight(kg): 1.364

Weight(gm): 1364

Size: 3"

Color: CLEAR

Material: PVC

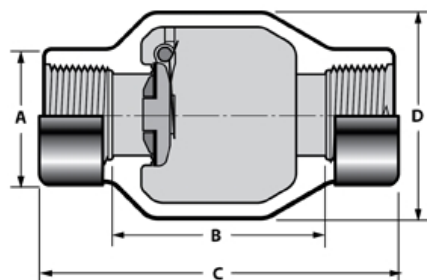

Type Utility Spring Check
Connection SR Fipt
Body Color Clear
Pressure Rating 150 psi @ 73° F Full Flow (Open)
 75 psi Back Pressure (Closed)

A = 4- 5/16

B = 6-3/16

C = 8-7/8

D = 5- 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

