

Part No: S1720C15F

Valves

Swing & Spring Check

Desc: 1-1/2 PVC CL TU UTLTY SW CK VLV THD EPDM

MSRP: 51.78

Part Code: 026

Weight(lbs): 1.31

Weight(kg): 0.594

Weight(gm): 594

Size: 1-1/2"

Color: CLEAR


Material: PVC

Type Utility Swing Check

Connection Fipt (TU)

Body Color Clear

Pressure Rating 150 psi @ 73° F Full Flow (Open)
75 psi Back Pressure (Closed)

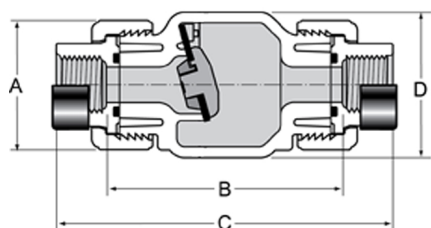

A = 33-5/8

B = 4-23/32

C = 6- 1/2

D = 3- 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

