

Part No: S1720C40FSR

Valves

Swing & Spring Check

Desc: 4 PVC CL TU UTILITY SW CK VLV SRTHD EPDM

MSRP: 259.71

Part Code: 026

Weight(lbs): 9.998

Weight(kg): 4.535

Weight(gm): 4535

Size: 4"

Color: CLEAR


Material: PVC

Type Utility Swing Check

Connection SR Fipt (TU)

Body Color Clear

Pressure Rating 150 psi @ 73° F Full Flow (Open)
75 psi Back Pressure (Closed)

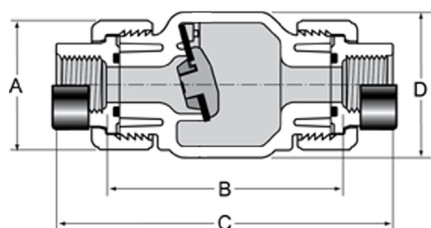

A = 7-11/16

B = 9-9/16

C = 12-7/16

D = 7- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

