

Part No: S854-020

Flanges & Cut-In Kit

Molded

Desc: 2 PVC V/S FLANGE SOC CL150 SOLID STYLE

MSRP: 63.27

Part Code: 080

Weight(lbs): 0.963

Weight(kg): 0.437


Weight(gm): 437

Size: 2

Color: GRAY

Material: PVC

Connection Socket (Van Stone Solid Ring)

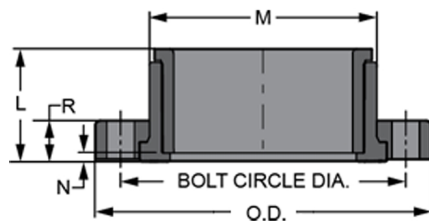

L = 1-21/32

M = 2-31/32

N = 5/32

O.D. = 6

R = 7/8

No of Bolts = 4

Bolt Circle Dia. = 4-3/4

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

