

Part No: S854-040

Flanges & Cut-In Kit

Molded

Desc: 4 PVC V/S FLANGE SOC CL150 SOLID STYLE

MSRP: 136.63

Part Code: 080

Weight(lbs): 2.308

Weight(kg): 1.047


Weight(gm): 1047

Size: 4

Color: GRAY

Material: PVC

Connection Socket (Van Stone Solid Ring)

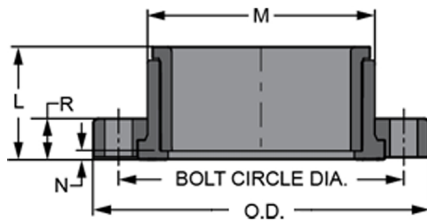

L = 2- 1/2

M = 5- 1/4

N = 1/4

O.D. = 9-3/32

R = 1-3/16

No of Bolts = 8

Bolt Circle Dia. = 7- 1/2

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

