

**Part No:** S854-080

**Flanges & Cut-In Kit**

**Molded**

**Desc:** 8 PVC V/S FLANGE SOC CL150 SOLID STYLE

**MSRP:** 349.91

**Part Code:** 080

**Weight(lbs):** 5.959

**Weight(kg):** 2.703


**Weight(gm):** 2703

**Size:** 8

**Color:** GRAY

**Material:** PVC

**Connection** Socket (Van Stone Solid Ring)

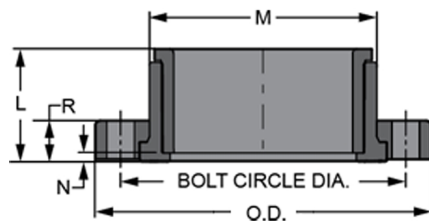

**L** = 4- 3/8

**M** = 9-15/32

**N** = 9/32

**O.D.** = 13-9/16

**R** = 1-15/32

**No of Bolts** = 8

**Bolt Circle Dia.** = 11- 3/4

**Bolt Size** = 3/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

