

Part No: S854-120

Flanges & Cut-In Kit

Molded

Desc: 12 PVC V/S FLANGE SOC CL150 SOLID STYLE

MSRP: 488.4

Part Code: 081

Weight(lbs): 15.968

Weight(kg): 7.243


Weight(gm): 7243

Size: 12

Color: GRAY

Material: PVC

Connection Socket (Van Stone Solid Ring)

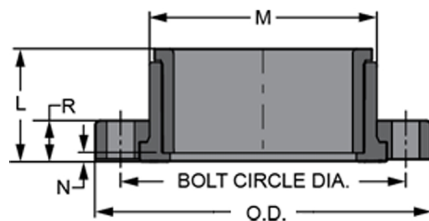

L = 6-19/32

M = 13- 3/4

N = 5/8

O.D. = 19

R = 1-13/16

No of Bolts = 12

Bolt Circle Dia. = 17

Bolt Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

