

Part No: SG118-07CO

FlameGuard®

GripLoc™ Repair Coupling

Desc: 3/4 CPVC FG GRIPLOC REPAIR COUPLING

MSRP: 48.8

Part Code: 134

Weight(lbs): 0.655


Weight(kg): 0.297

Weight(gm): 297

Size: 3/4

Color: ORANGE

Material: CPVC

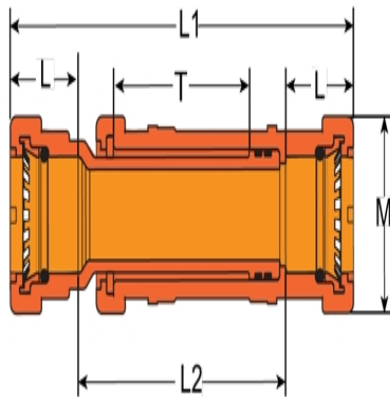

Type GripLoc™
Connection GripLoc™ Socket
O-Ring EPDM
WARNING DO NOT INSERT FINGERS
Pressure Rating 175 psi (1.21 Mpa) @ 150° F
Note Use NO Solvent Cement
NSF® Certified LEAD FREE

L = 1-1/2

L1 = 7-9/16

L2 = 4-1/2

M = 1-29/32

T = 2-15/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

