

Part No: SG118-10CO

FlameGuard®

GripLoc™ Repair Coupling

Desc: 1 CPVC ORANGE FG GRIPLOC REPAIR COUPLING

MSRP: 55.24

Part Code: 134

Weight(lbs): 0.721


Weight(kg): 0.327

Weight(gm): 327

Size: 1

Color: ORANGE

Material: CPVC

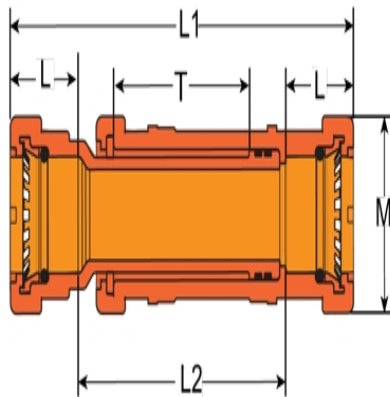

Type GripLoc™
Connection GripLoc™ Socket
O-Ring EPDM
WARNING DO NOT INSERT FINGERS
Pressure Rating 175 psi (1.21 Mpa) @ 150° F
Note Use NO Solvent Cement
NSF® Certified LEAD FREE

L = 1-1/2

L1 = 7-7/16

L2 = 4-7/16

M = 2-5/16

T = 3

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

