

Part No: SH118-10T

EverTUFF® TURF™

Repair Couplings

Desc: 1 PVC SHORT REPAIR COUP CL315 SPIGOTXSOC

MSRP: 20.42

Part Code: 031

Weight(lbs): 0.428

Weight(kg): 0.194

Weight(gm): 194

Size: 1 PVC SHORT REPAIR COUP

Color: BLUE


Material: PVC

Connection Spigot x Socket

Type Short Repair Coupling

O-Ring EPDM

Pressure Rating Class 315

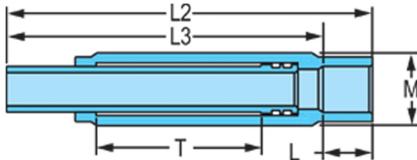

L = 15/16

L2 = 5-11/16

L3 = 4-3/4


M = 2-1/16

T = 2

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

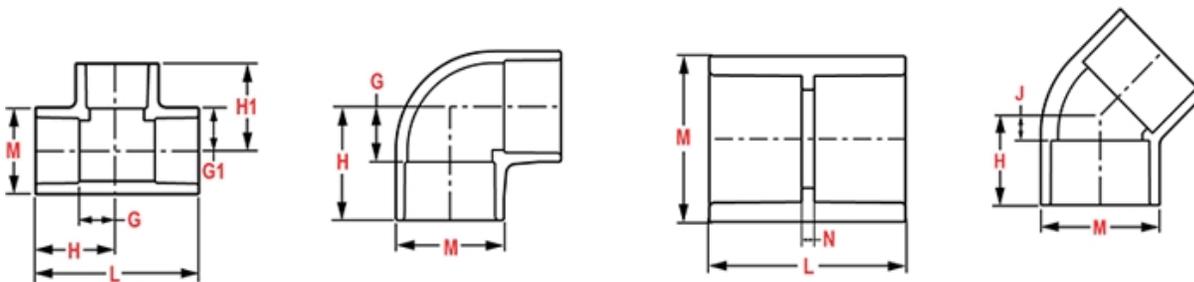

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006