

Part No: SH118-12T

EverTUFF® TURF™

Repair Couplings

Desc: 1-1/4 PVC SHORT RPR COUP CL315 SPGXSOC

MSRP: 38.48

Part Code: 031

Weight(lbs): 0.608

Weight(kg): 0.276

Weight(gm): 276

Size: 1-1/4 PVC SHORT RPR COUP

Color: BLUE


Material: PVC

Connection Spigot x Socket

Type Short Repair Coupling

O-Ring EPDM

Pressure Rating Class 315

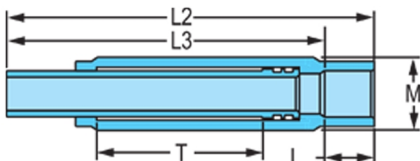

L = 1

L2 = 6-9/16

L3 = 5-9/16

M = 2-7/16

T = 2-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

