

Part No: SS23BS4SG-040

Filters & Strainers

Suction Strainers

Desc: 4 PVC SUCTION STRAINER FLANGED EPDM

MSRP: 5005.34

Part Code: 295

Weight(lbs): 76.653


Weight(kg): 34.769

Weight(gm): 34769

Size: 4

Color: GRAY

Material: PVC

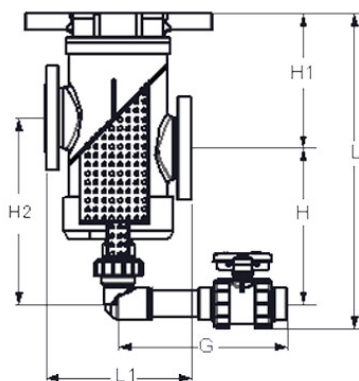

Type Suction
Connection Flanged
O-Ring EPDM
Pressure Rating 50 psi @ 73° F

G = 14-13/16

H = 15-7/8

H1 = 11-13/16

H2 = 18-9/16

L = 29-15/16

L1 = 12- 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

