

Part No: SS23BS4SG-060

Filters & Strainers

Suction Strainers

Desc: 6 PVC SUCTION STRAINER FLANGED EPDM

MSRP: 6529

Part Code: 295

Weight(lbs): 79.267


Weight(kg): 35.955

Weight(gm): 35955

Size: 6"

Color: GRAY

Material: PVC

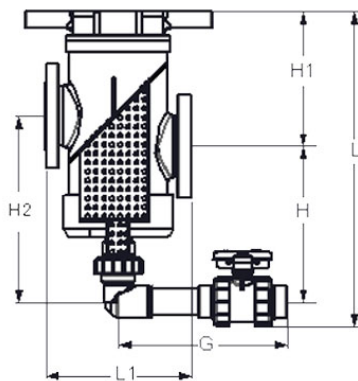

Type Suction
Connection Flanged
O-Ring EPDM
Pressure Rating 50 psi @ 73° F

G = 14-13/16

H = 19-1/16

H1 = 13-9/16

H2 = 22-1/8

L = 32-11/16

L1 = 15-7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

