

Part No: SS23BS4SG-080

Filters & Strainers

Suction Strainers

Desc: 8 PVC SUCTION STRAINER FLANGED EPDM

MSRP: 7171.22

Part Code: 295

Weight(lbs): 120.044


Weight(kg): 54.451

Weight(gm): 54451

Size: 8

Color: GRAY

Material: PVC

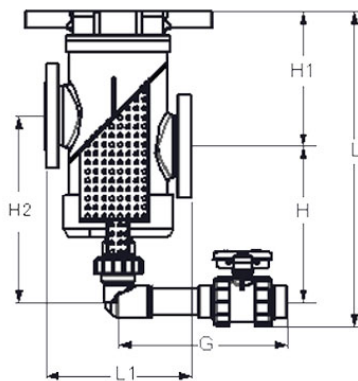

Type Suction
Connection Flanged
O-Ring EPDM
Pressure Rating 50 psi @ 73° F

G = 17-15/16

H = 23-13/16

H1 = 18-1/8

H2 = 29-7/16

L = 44-1/8

L1 = 18

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

