

Part No: TF2-16C

Filters & Strainers

Irrigation Filters

Desc: 100 GPM CPVC IND T-FILTR 16 MESH SS EPDM

MSRP: 1569.24

Part Code: 296

Weight(lbs): 11.341

Weight(kg): 5.144

Weight(gm): 5144

Size: 100 GPM

Color: GRAY

Material: CPVC

Under

Filter Type Socket

O-Ring EPDM

Mesh #16

Body Color Gray

Pressure Rating 200 psi @ 73° F

Style In-Line Tee


Flow Standard & Reverse

Development

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

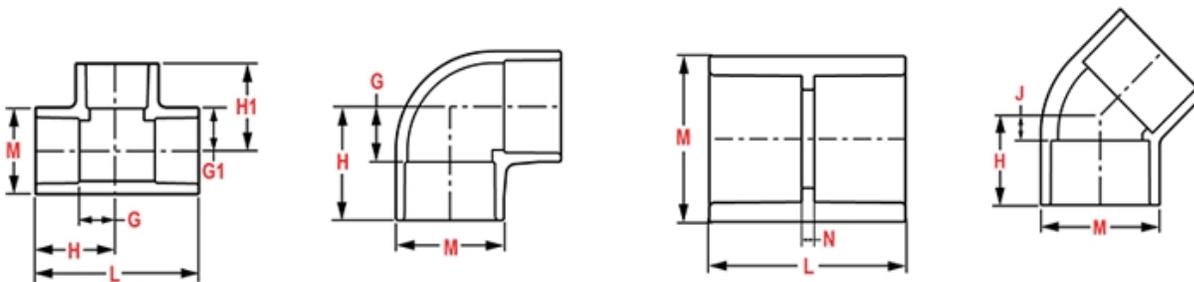

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006