

Part No: TPC-010-S

EverTUFF® CTS

PEX Transition Adapters

Desc: 1(1-1/4) CPVC CTS TRANS ADPT BRBXSOC

MSRP: 58.73

Part Code: 036

Weight(lbs): 0.112

Weight(kg): 0.051

Weight(gm): 51

Size: 1

Color: TAN


Material: CPVC

Connection Socket x SS PEX Barb - Crimp Style

Type PEX Transition Adapter

NSF® Certified LEAD FREE

NOTE ASTM F1807 Standard PEX Connector

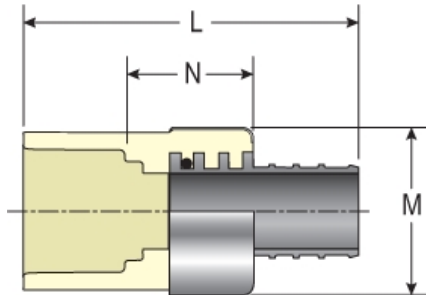

L = 2-9/32

M = 1-7/16

N = 19/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

