

Part No: YS21C8-020CSR

Filters & Strainers

Y-Strainers

Desc: 2 CPVC Y STRAINER SR/FPT EPDM C8 MESH

MSRP: 1261.03

Part Code: 104

Weight(lbs): 3.578

Weight(kg): 1.623

Weight(gm): 1623

Size: 2"

Color: GRAY


Material: CPVC

Connection SR Fipt

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

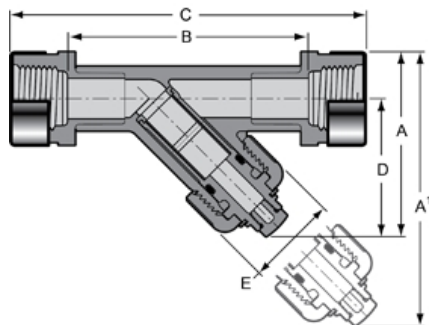

A = 7- 5/8

A1 = 12

B = 8- 1/8

C = 10- 1/8

D = 6- 3/16

E = 3- 1/2

Cv = 50.6
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

