

Part No: YS21S8-007CSR

Filters & Strainers

Y-Strainers

Desc: 3/4 CPVC Y STRAINER SR/FPT EPDM SS8 MESH

MSRP: 624.7

Part Code: 104

Weight(lbs): 0.668

Weight(kg): 0.303

Weight(gm): 303

Size: 3/4"

Color: GRAY


Material: CPVC

Connection SR Fipt

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

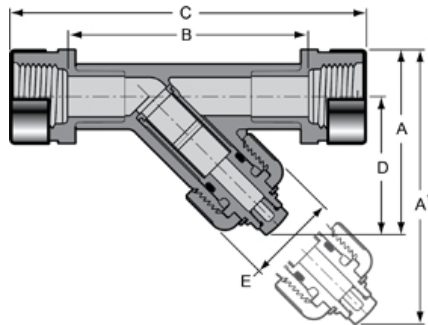

A = 3-11/16

A1 = 5-15/16

B = 4- 3/8

C = 5-13/16

D = 3

E = 2

Cv = 8.2
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

