

Part No: YS21S8-010CLSR

Filters & Strainers

Y-Strainers

Desc: 1 PVC CLR Y STRAINER SR/FPT EPDM S8 MESH

MSRP: 409.29

Part Code: 103

Weight(lbs): 0.897

Weight(kg): 0.407

Weight(gm): 407

Size: 1"

Color: CLEAR


Material: PVC

Connection SR Fipt

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

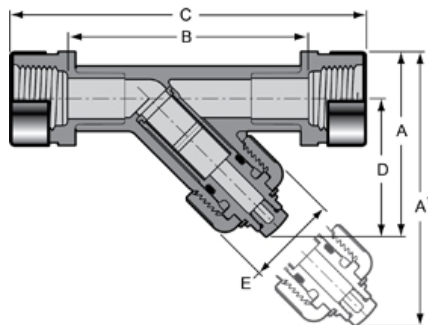

A = 4- 7/16

A1 = 7- 1/16

B = 5- 3/16

C = 7

D = 3- 5/8

E = 2- 1/4

Cv = 14.3
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

