

Part No: YS21S8-015CLSR

Filters & Strainers

Y-Strainers

Desc: 1-1/2 PVC CL Y STRAINER SR/FPT EPDM SS8M

MSRP: 637.26

Part Code: 103

Weight(lbs): 2.061

Weight(kg): 0.935

Weight(gm): 935

Size: 1-1/2"

Color: CLEAR


Material: PVC

Connection SR Fipt

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

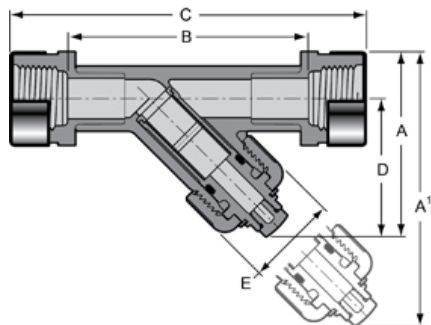

A = 6

A1 = 9- 3/8

B = 6-15/16

C = 8-13/16

D = 4- 7/8

E = 3- 3/16

Cv = 43.8
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

