

Part No: YS21S8-040CLSR

Filters & Strainers

Y-Strainers

Desc: 4 PVC CL Y STRAINER SR/FPT EPDM SS8 MESH

MSRP: 1983.19

Part Code: 103

Weight(lbs): 12.696

Weight(kg): 5.759

Weight(gm): 5759

Size: 4"

Color: CLEAR


Material: PVC

Connection SR Fipt

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

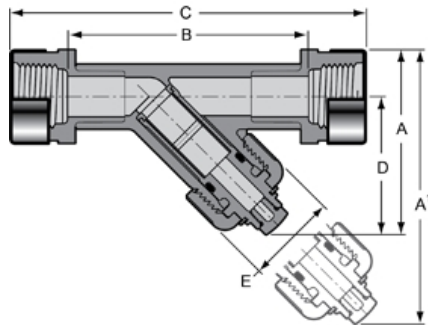

A = 12- 1/2

A1 = 19-13/16

B = 14

C = 14- 3/8

D = 9- 7/8

E = 6- 9/16

Cv = 169.5
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

