

Part No: YS22S8-020CL

Filters & Strainers

Y-Strainers

Desc: 2 PVC CL Y STRAINER SOC EPDM SS8 MESH

MSRP: 738.31

Part Code: 103

Weight(lbs): 2.661


Weight(kg): 1.207

Weight(gm): 1207

Size: 2"

Color: CLEAR

Material: PVC

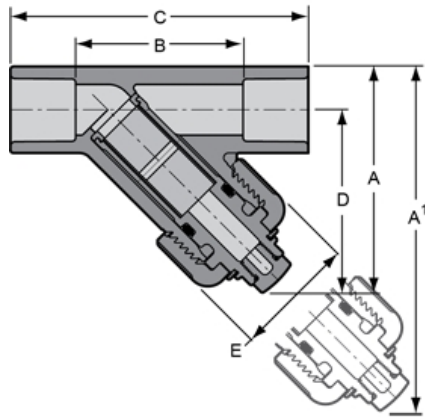

Connection Socket

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

A = 7- 5/8

A1 = 11- 3/4

B = 4- 1/2

C = 7- 1/2

D = 6- 3/16

E = 3- 1/2

Cv = 50.6
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

