

Part No: YS23P8-012CL

Filters & Strainers

Y-Strainers

Desc: 1-1/4 PVC CL Y-STRAINER FLANGED EPDM P8M

MSRP: 434.52

Part Code: 103

Weight(lbs): 2.061

Weight(kg): 0.935

Weight(gm): 935

Size: 1-1/4"

Color: CLEAR


Material: PVC

Connection Flanged

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

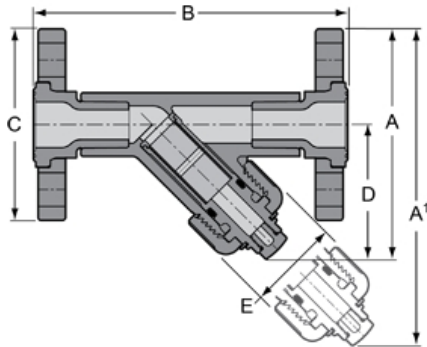

A = 6- 9/16

A1 = 9- 7/16

B = 8- 1/8

C = 4- 5/8

D = 4- 9/32

E = 2-13/16

Cv = 33.6
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

