

Part No: YS23S8-007CL

Filters & Strainers

Y-Strainers

Desc: 3/4 PVC CL Y-STRAINER FLANGED EPDM S8MSH

MSRP: 461.48

Part Code: 103

Weight(lbs): 1.032

Weight(kg): 0.468

Weight(gm): 468

Size: 3/4"

Color: CLEAR


Material: PVC

Connection Flanged

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

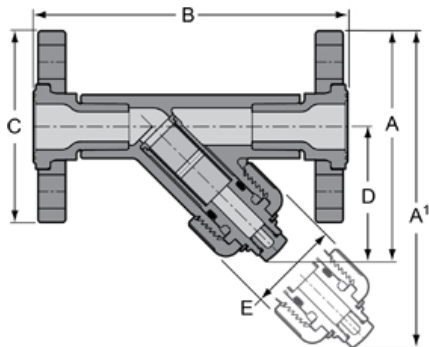

A = 5- 1/16

A1 = 7- 1/8

B = 6- 7/16

C = 3- 7/8

D = 3- 1/8

E = 2

Cv = 8.2
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

