

Part No: YS23S8-030CL

Filters & Strainers

Y-Strainers

Desc: 3 PVC CL Y STRAINER FLANGED EPDM S8 MESH

MSRP: 1650.38

Part Code: 103

Weight(lbs): 9.423

Weight(kg): 4.274

Weight(gm): 4274

Size: 3"

Color: CLEAR


Material: PVC

Connection Flanged

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

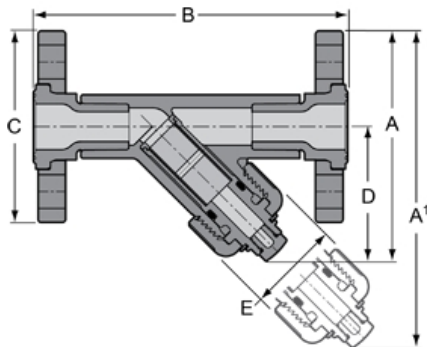

A = 11- 3/8

A1 = 16-21/32

B = 12- 1/32

C = 7- 1/2

D = 7- 5/8

E = 5- 1/8

Cv = 75.2
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

