

Part No: YS2AS8-007C

Filters & Strainers

Y-Strainers

Desc: 3/4 CPVC T/U Y STRAINER SOC EPDM S8 MESH

MSRP: 641.63

Part Code: 104

Weight(lbs): 0.957

Weight(kg): 0.434

Weight(gm): 434

Size: 3/4"

Color: GRAY


Material: CPVC

Connection Socket - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

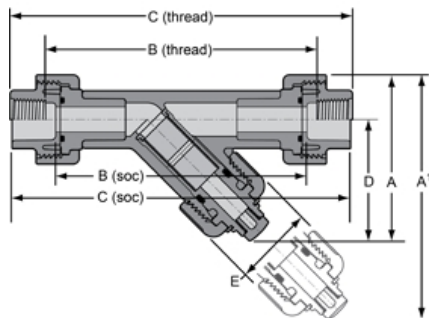

A = 4-1/8

A1 = 6-3/16

B = 5-7/8

C = 7-7/8

D = 3

E = 2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

