

Part No: YS2AS8-015CL

Filters & Strainers

Y-Strainers

Desc: 1-1/2 PVC CL T/U Y STRAINER SOC EPDM S8M

MSRP: 635.3

Part Code: 103

Weight(lbs): 2.648

Weight(kg): 1.201

Weight(gm): 1201

Size: 1-1/2"

Color: CLEAR


Material: PVC

Connection Socket - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

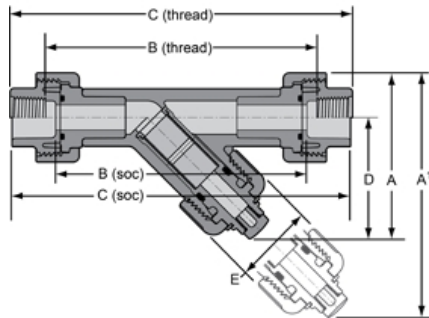

A = 6-5/8

A1 = 9-3/4

B = 8-3/16

C = 10-15/16

D = 4-7/8

E = 3-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

