

Part No: YS2AS8-040

Filters & Strainers

Y-Strainers

Desc: 4 PVC T/U Y STRAINER SOC EPDM S8 MESH

MSRP: 2007.84

Part Code: 102

Weight(lbs): 19.403

Weight(kg): 8.801

Weight(gm): 8801

Size: 4"

Color: GRAY


Material: PVC

Connection Socket - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

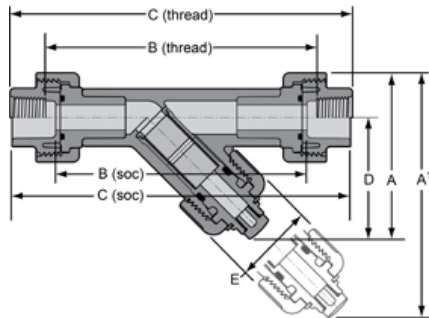

D = 9-7/8

E = 6-9/16

A = 13-3/4

A1 = 20-15/16

B = 15-5/16

C = 19-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

