

Part No: YS2BC8-015CSR

Filters & Strainers

Y-Strainers

Desc: 1-1/2 CPVC T/U Y STRAINER SRFPT EPDM C8M

MSRP: 937.23

Part Code: 104

Weight(lbs): 2.87

Weight(kg): 1.302

Weight(gm): 1302

Size: 1-1/2

Color: GRAY


Material: CPVC

Connection SR Fipt - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

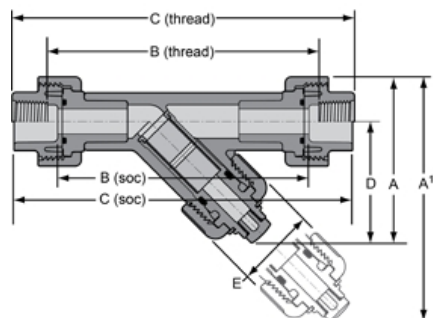

A = 6-5/8

A1 = 9-3/4

B = 9

C = 10-15/16

D = 4-7/8

E = 3-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

