

Part No: YS2BC8-040C

Filters & Strainers

Y-Strainers

Desc: 4 CPVC T/U Y STRAINER FPT EPDM C8 MESH

MSRP: 2614.43

Part Code: 104

Weight(lbs): 20.514

Weight(kg): 9.305

Weight(gm): 9305

Size: 4"

Color: GRAY


Material: CPVC

Connection Fipt - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

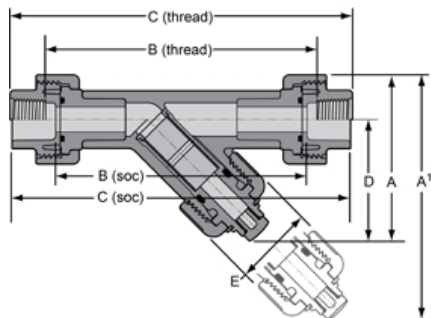

A = 13-3/4

A1 = 20-15/16

B = 17-1/2

C = 20-1/2

D = 9-7/8

E = 6-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

