

Part No: YS2BS8-012CL

Filters & Strainers

Y-Strainers

Desc: 1-1/4 PVC CL T/U Y STRAINER FPT EPDM S8M

MSRP: 595.98

Part Code: 103

Weight(lbs): 2.013

Weight(kg): 0.913

Weight(gm): 913

Size: 1-1/4"

Color: CLEAR


Material: PVC

Connection Fipt - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Clear

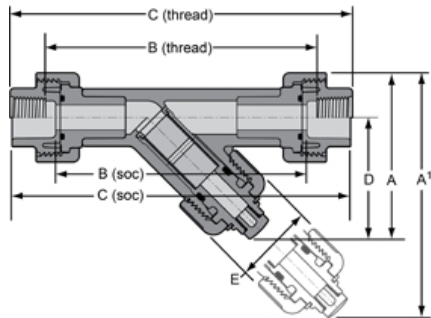

A = 5-13/16

A1 = 8-5/8

B = 6-3/16

C = 10-1/8

D = 4-1/4

E = 2-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

