

Part No: YS2BS8-030C

Filters & Strainers

Y-Strainers

Desc: 3 CPVC T/U Y STRAINER FPT EPDM S8 MESH

MSRP: 1805.66

Part Code: 104

Weight(lbs): 11.7

Weight(kg): 5.307

Weight(gm): 5307

Size: 3"

Color: GRAY


Material: CPVC

Connection Fipt - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

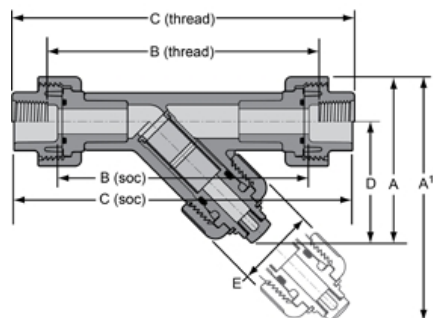

A = 10-3/4

A1 = 16-1/6

B = 13-15/16

C = 16-3/4

D = 7-5/8

E = 5-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

