

Part No: YS2BS8-030CSR

Filters & Strainers

Y-Strainers

Desc: 3 CPVC T/U Y STRAINER SR/FPT EPDM S8MESH

MSRP: 1882.54

Part Code: 104

Weight(lbs): 11.77

Weight(kg): 5.339

Weight(gm): 5339

Size:

Color: GRAY


Material: CPVC

Connection SR Fipt - True Union

O-Ring EPDM

Mesh Sieve # 8

Body Color Gray

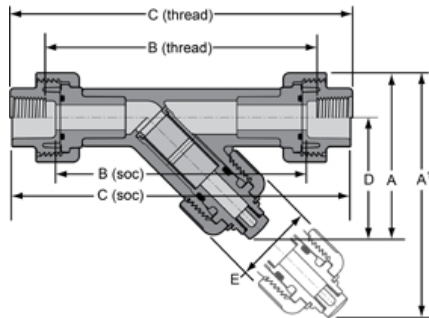

A1 = 16-1/6

B = 13-15/16

C = 16-3/4

D = 7-5/8

E = 5-1/8

A = 10-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

