

Part No: YS31S8-015CSR

Filters & Strainers

Y-Strainers

Desc: 1-1/2 CPVC Y STRAINER SR/FPT FKM S8 MESH

MSRP: 1297.67

Part Code: 104

Weight(lbs): 2.22

Weight(kg): 1.007

Weight(gm): 1007

Size: 1-1/2"

Color: GRAY


Material: CPVC

Connection SR Fipt

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

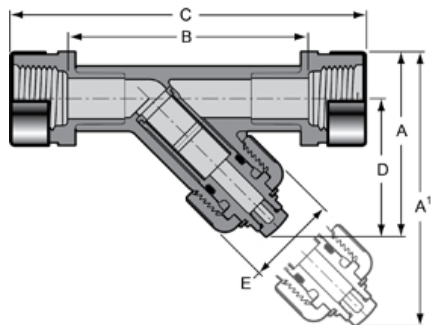

A = 6

A' = 9-3/8

B = 6-15/16

C = 8-13/16

D = 4-7/8

E = 3-3/16

Cv = 43.8
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

