

Part No: YS31S8-030CSR

Filters & Strainers

Y-Strainers

Desc: 3 CPVC Y STRAINER SR/FPT FKM SS8 MESH

MSRP: 1918.24

Part Code: 104

Weight(lbs): 7.941

Weight(kg): 3.602

Weight(gm): 3602

Size: 3"

Color: GRAY


Material: CPVC

Connection SR Fipt

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

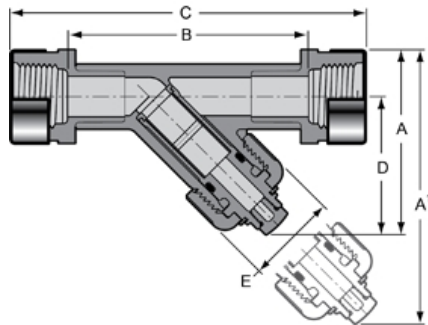

A = 9-11/16

A1 = 15- 5/16

B = 11

C = 14- 1/4

D = 7- 5/8

E = 5- 1/8

Cv = 75.2
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

