

Part No: YS33P8-015

Filters & Strainers

Y-Strainers

Desc: 1-1/2 PVC Y-STRAINER FLANGED FKM P8 MESH

MSRP: 537.67

Part Code: 102

Weight(lbs): 2.773


Weight(kg): 1.258

Weight(gm): 1258

Size: 1-1/2"

Color: GRAY

Material: PVC

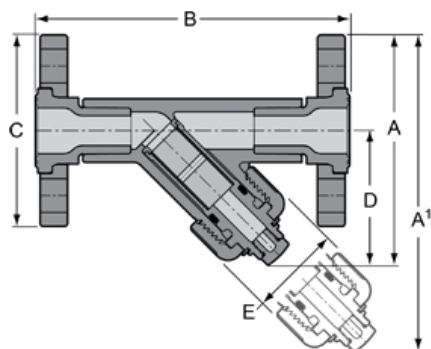

Connection Flanged

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

A = 7- 3/8

A1 = 10- 7/16

B = 9- 3/16

C = 5

D = 4- 7/8

E = 3- 3/16

Cv = 43.8
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

