

Part No: YS33S8-012C

Filters & Strainers

Y-Strainers

Desc: 1-1/4 CPVC Y-STRAINER FLANGED FKM S8MESH

MSRP: 1567.32

Part Code: 104

Weight(lbs): 2.293


Weight(kg): 1.04

Weight(gm): 1040

Size: 1-1/4"

Color: GRAY

Material: CPVC

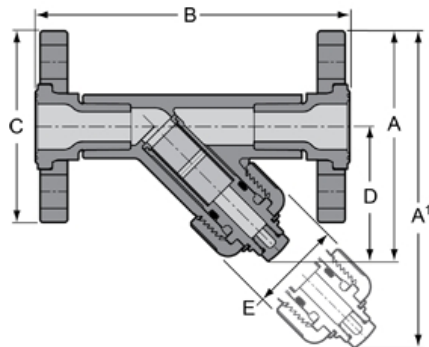

Connection Flanged

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

A = 6- 9/16

A1 = 9- 7/16

B = 8- 1/8

C = 4- 5/8

D = 4- 9/32

E = 2-13/16

Cv = 33.6
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

