

Part No: YS3AP8-020CL

Filters & Strainers

Y-Strainers

Desc: 2 PVC CL T/U Y STRAINER SOC FKM P8 MESH

MSRP: 442.08

Part Code: 103

Weight(lbs): 4.319

Weight(kg): 1.959

Weight(gm): 1959

Size: 2"

Color: CLEAR


Material: PVC

Connection Socket - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Clear

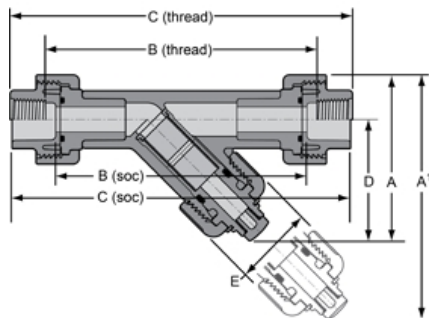

B = 9-7/16

C = 12-7/16

D = 6-3/16

E = 3-1/2

A = 8-15/16

A1 = 12-7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

