

Part No: YS3AS8-005CL

Filters & Strainers

Y-Strainers

Desc: 1/2 PVC CL T/U Y STRAINER SOC FKM S8MESH

MSRP: 334.59

Part Code: 103

Weight(lbs): 0.553

Weight(kg): 0.251

Weight(gm): 251

Size: 1/2"

Color: CLEAR


Material: PVC

Connection Socket - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Clear

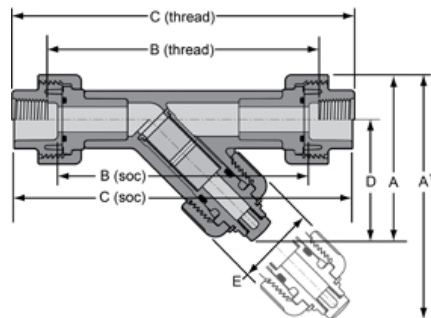

A = 3-7/16

A1 = 5

B = 5-1/8

C = 6-7/8

D = 2-1/2

E = 1-5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

