

Part No: YS3AS8-010CL

Filters & Strainers

Y-Strainers

Desc: 1 PVC CL T/U Y STRAINER SOC FKM SS8 MESH

MSRP: 454.16

Part Code: 103

Weight(lbs): 1.259

Weight(kg): 0.571

Weight(gm): 571

Size: 1"

Color: CLEAR


Material: PVC

Connection Socket - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Clear

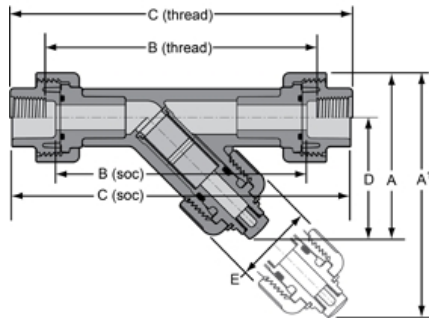

A = 4-7/8

A1 = 7-5/16

B = 6-1/2

C = 8-3/4

D = 3-5/8

E = 2-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

