

Part No: YS3BC8-020CSR

Filters & Strainers

Y-Strainers

Desc: 2 CPVC T/U Y STRAINER SR/FPT FKM C8 MESH

MSRP: 1487.87

Part Code: 104

Weight(lbs): 4.883

Weight(kg): 2.215

Weight(gm): 2215

Size:

Color: GRAY


Material: CPVC

Connection SR Fipt - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

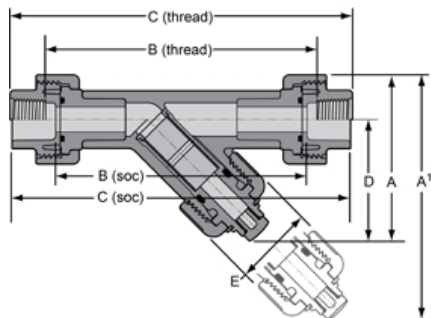

E = 3-1/2

A = 8-15/16

A1 = 12-7/16

B = 10-13/16

C = 12-13/16

D = 6-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References



The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006