

Part No: YS3BP8-015CLSR

Filters & Strainers

Y-Strainers

Desc: 1-1/2 PVC CL T/U Y STRAINER SRFPT FKM P8

MSRP: 411.84

Part Code: 103

Weight(lbs): 2.718

Weight(kg): 1.233

Weight(gm): 1233

Size:

Color: CLEAR


Material: PVC

Connection SR Fipt - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Clear

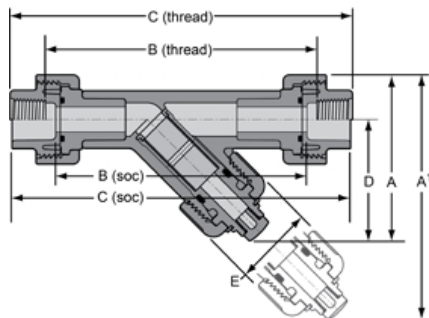

B = 9

C = 10-15/16

D = 4-7/8

E = 3-3/16

A = 6-5/8

A1 = 9-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

