

Part No: YS3BP8-030

Filters & Strainers

Y-Strainers

Desc: 3 PVC T/U Y STRAINER FPT FKM P8 MESH

MSRP: 985.41

Part Code: 102

Weight(lbs): 10.56

Weight(kg): 4.79

Weight(gm): 4790

Size: 3"


Color: GRAY

Material: PVC

Connection Fipt - True Union

Mesh Sieve # 8

Body Color Gray

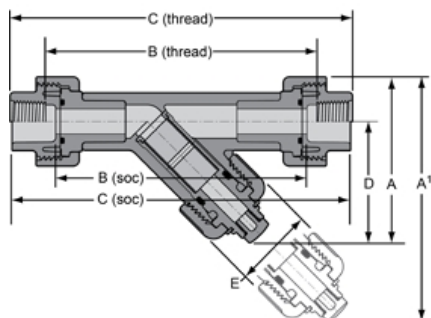

A = 10-3/4

A1 = 16-1/6

B = 13-15/16

C = 16-3/4

D = 7-5/8

E = 5-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

