

Part No: YS3BP8-040CL

Filters & Strainers

Y-Strainers

Desc: 4 PVC CL T/U Y STRAINER FPT FKM P8 MESH

MSRP: 1725.84

Part Code: 103

Weight(lbs): 18.801

Weight(kg): 8.528

Weight(gm): 8528

Size: 4"

Color: CLEAR


Material: PVC

Connection Fipt - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Clear

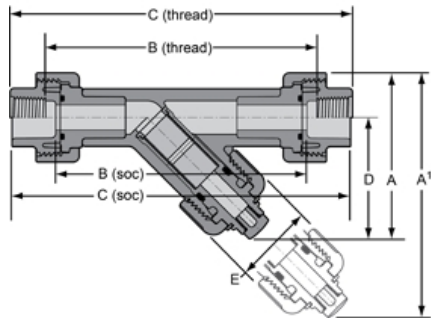

D = 9-7/8

E = 6-9/16

A = 13-3/4

A1 = 20-15/16

B = 17-1/2

C = 20-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

