

Part No: YS3BP8-040CLSR

Filters & Strainers

Y-Strainers

Desc: 4 PVC CL T/U Y STRAINER SR/FPT FKM P8MSH

MSRP: 1805.66

Part Code: 103

Weight(lbs): 18.854

Weight(kg): 8.552

Weight(gm): 8552

Size:

Color: CLEAR


Material: PVC

Connection SR Fipt - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Clear

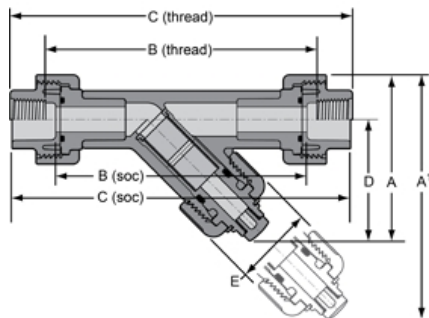

A = 13-3/4

A1 = 20-15/16

B = 17-1/2

C = 20-1/2

D = 9-7/8

E = 6-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

