

Part No: YS3BS8-005CSR

Filters & Strainers

Y-Strainers

Desc: 1/2 CPVC T/U Y STRAINER SR/FPT FKM S8MSH

MSRP: 649.13

Part Code: 104

Weight(lbs): 0.615

Weight(kg): 0.279

Weight(gm): 279

Size:

Color: GRAY


Material: CPVC

Connection SR Fipt - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

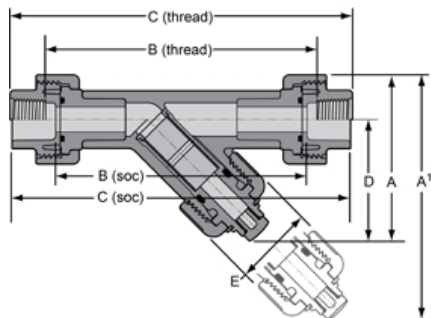

E = 1-5/8

A = 3-7/16

A1 = 5

B = 5-1/2

C = 7

D = 2-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

