

**Part No:** YS3BS8-010CLSR

**Filters & Strainers**

**Y-Strainers**

**Desc:** 1 PVC CL T/U Y STRAINER SR/FPT FKM S8MSH

**MSRP:** 471.91

**Part Code:** 103

**Weight(lbs):** 1.321

**Weight(kg):** 0.599

**Weight(gm):** 599

**Size:** 1

**Color:** CLEAR


**Material:** PVC

**Connection** SR Fipt - True Union

**O-Ring** FKM

**Mesh Sieve** # 8

**Body Color** Clear

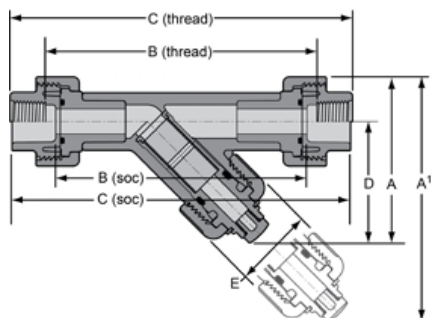

**A** = 4-7/8

**A1** = 7-5/16

**B** = 7-3/8

**C** = 9

**D** = 3-5/8

**E** = 2-1/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

