

Part No: YS3BS8-012C

Filters & Strainers

Y-Strainers

Desc: 1-1/4 CPVC T/U Y STRAINER FPT FKM S8MESH

MSRP: 1212.49

Part Code: 104

Weight(lbs): 2.191

Weight(kg): 0.994

Weight(gm): 994

Size: 1-1/4"

Color: GRAY


Material: CPVC

Connection Fipt - True Union

O-Ring FKM

Mesh Sieve # 8

Body Color Gray

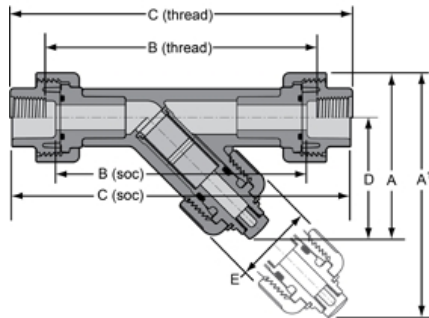

D = 4-1/4

E = 2-13/16

A = 5-13/16

A1 = 8-5/8

B = 6-3/16

C = 10-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

