

Product data sheet

Specifications

SQUARE D

Green Premium™



Transformer, Type T, industrial control, 200VA, 1 phase, 240x480V primary, 120V secondary, 80C rise

9070T200D1

Product availability : Stock - Normally stocked in distribution facility

Price* : 246.00 USD

Main

Product Type Industrial Control Transformer

Type T

Complementary

Number of Phases 1 phase

Power Rating 200 VA UL
200 VA CSA
200 VA NOM
200 VA CE

Primary to Secondary Voltage 240 x 480 V 120 V
230 x 460 V 115 V
220 x 440 V 110 V

Temperature Rise 80 °C

Electrical Connection Screw clamp terminals

Height 3.2 in (81.28 mm)

Width 3.75 in (95.25 mm)

Depth 3.59 in (91.19 mm)

Material Copper winding

Fingersafe Cover Compatibility FSC1

Environment

Certifications UL listed file E61239
CSA file LR37055 guide 184-N-90

Enclosure Type Not rated (open device)

Insulation Temperature 266 °F (130 °C)

Ordering and shipping details

Category 16200-9070 T (NOT TF) 50-200VA

Discount Schedule CP8

GTIN 785901904663

Returnability Yes

Country of origin MX

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.25 in (8.255 cm)
Package 1 Width	3.60 in (9.144 cm)
Package 1 Length	3.75 in (9.525 cm)
Package 1 Weight	5.60 lb(US) (2.54 kg)
Unit Type of Package 2	PAL
Number of Units in Package 2	450
Package 2 Height	40.00 in (101.6 cm)
Package 2 Width	40.00 in (101.6 cm)
Package 2 Length	48.00 in (121.92 cm)
Package 2 Weight	2520.00 lb(US) (1143.052 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Phenyl glycidyl ether, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
PVC free	Yes

Contractual warranty

Warranty	10 Years
----------	----------

Dimensions

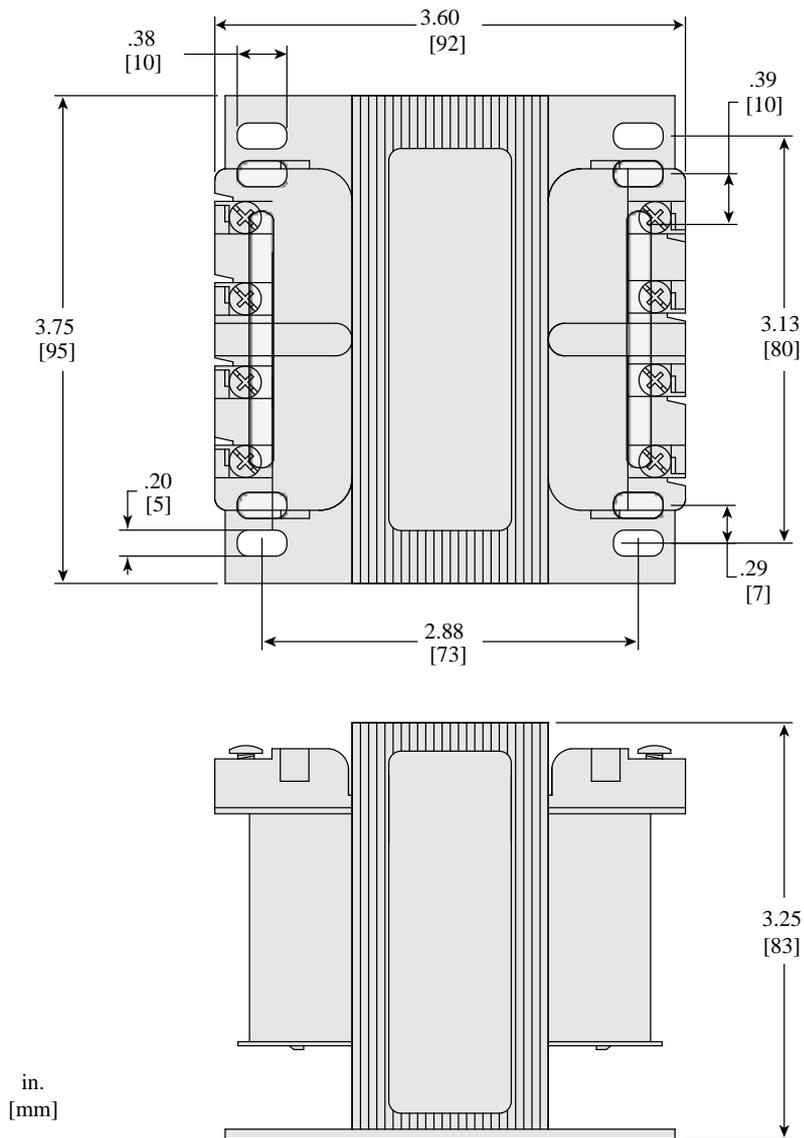

Recommended replacement(s)