

Product data sheet

Specifications

SQUARE D



Power distribution block, Linergy, 2 pole, 1 line, 1 load, 310 CU, 250A AL, 600 V

9080LBA263101

Product availability : Stock - Normally stocked in distribution facility

Price* : 81.00 USD

Main

Range	9080LB
Product	Power Distribution Block
Current Rating	310 A copper 250 A aluminium

Complementary

Voltage Rating	600 V AC/DC
Mounting Type	Surface mount
Number of poles	2
Terminals per Pole	1 line 1 load
Wire Size	Line 1, AWG 6...350 kcmil, copper or aluminium Load 1, AWG 6...350 kcmil, copper or aluminium
Electrical Connection	Tin plated aluminium lugs
SCCR	100 kA UL 508 A
Ambient Air Temperature for Operation	-40...302 °F (-40...150 °C)
Block Material	Phenolic block
Terminal Tightening Torque	Line lug 275 lbf.in (31.07 N.m) AWG 6...350 kcmil copper or aluminium Load lug 275 lbf.in (31.07 N.m) AWG 6...350 kcmil copper or aluminium
Wire stripping length	Line 1.06 in (26.92 mm) Load 1.06 in (26.92 mm)
Height	3.38 in (85.85 mm)
Width	1.94 in (49.28 mm)
Depth	2.61 in (66.29 mm)
End Barrier	9080LB32

Environment

Certifications	CE UL recognized E60616 CCN XCFR2 CSA file 70361 class 6228 01
----------------	--

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ordering and shipping details

Category	21711-9080 LB
Discount Schedule	CP1
GTIN	785901156987
Returnability	Yes
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.00 in (7.62 cm)
Package 1 Width	4.30 in (10.922 cm)
Package 1 Length	5.30 in (13.462 cm)
Package 1 Weight	17.60 oz (498.952 g)
Unit Type of Package 2	CAR
Number of Units in Package 2	16
Package 2 Height	11.10 in (28.194 cm)
Package 2 Width	9.50 in (24.13 cm)
Package 2 Length	13.40 in (34.036 cm)
Package 2 Weight	18.36 lb(US) (8.328 kg)


Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

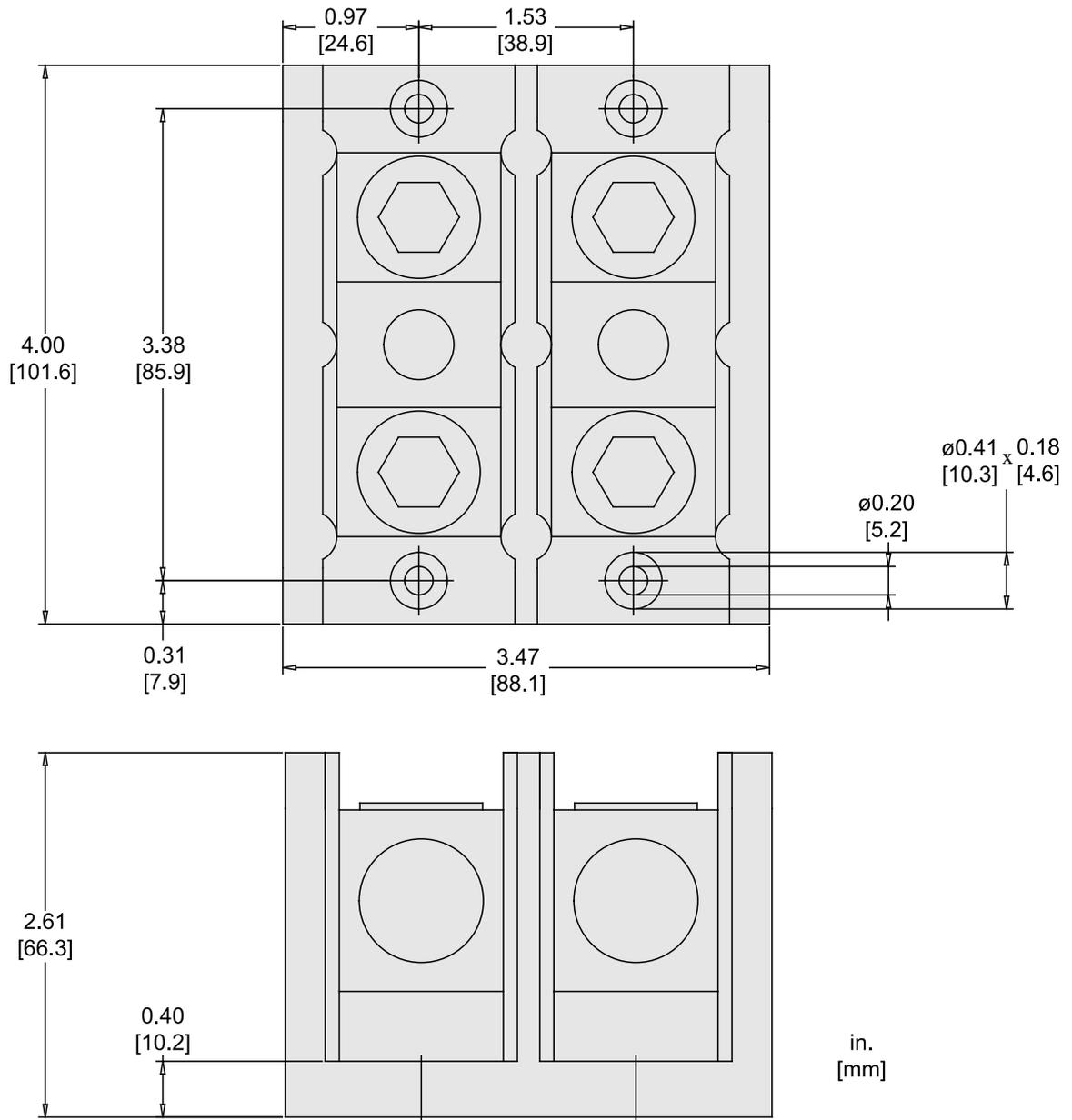

9080LBA263101

Recommended replacement(s)